
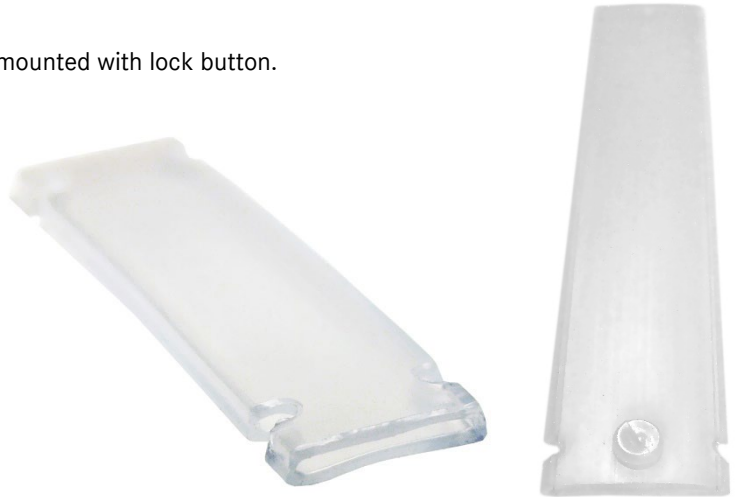


	<b>DATA SHEET</b>	
Valid from: 28-01-2019	<b>FLEXIMARK® character holders PTEF</b>	

Cable, pipe and component marking on site.  
Indoor and outdoor environment.  
Used together with FLEXIMARK® Marking system and 3M™ DYMO™ Industrial marking labels.  
Available in different widths and lengths.  
Premade holes for mounting with plastic cable ties.  
FLEXIMARK® PTEF 9,5-18 with lock button is delivered mounted with lock button.



**Technical data**

Material:	Polyethylene, halogen free
Operating temperature:	-75°C up to +80°C
Resistance:	UV-resistant
Recommended storage:	Cool and dry in original packaging

**Mounting:**

FLEXIMARK® Character holders are be used for cable marking and mounted with cable ties.

**Other product data:**

ETIM Classification:	EC001288
----------------------	----------


**Advantages:**

Produce marking on site when need it.  
Easy marking together with 3M™ DYMO™ Industrial marking labels and FLEXIMARK® Marking systems.  
Halogen free material.  
Cable and component marking for indoor and outdoor.  
Delivered with premade holes for mounting with plastic cable ties.  
Many different lengths and widths available in the assortment.

**Delivery:**


Delivered in packages with different lengths and widths.

Creator: Fleximark/LR	Document: DB83254970EN FLEXIMARK Character holder PTEF Version: 02	Page 1 of 3
-----------------------	-----------------------------------------------------------------------	-------------


	<b>DATA SHEET</b>	
Valid from: 28-01-2019	<b>FLEXIMARK® character holders PTEF</b>	

**Product data:**

E-nummer	LAPP Part no.	Article designation	Width (mm)	Text length (mm)	Length (mm)	Content (unit)	PU
2972157	83254970	Character holder PTEF 6-18	6	18	30	50	1
2972180	83254971	Character holder PTEF 6-28	6	28	40	50	1
2972181	83254974	Character Holder PTEF 6-35	6	35	47	50	1
2989409	83254972	Character Holder PTEF 6-38	6	38	50	50	1
2972182	83254973	Character Holder PTEF 6-58	6	58	70	50	1
2972183	83254960	Character Holder PTEF 9.5-18	9,5	18	30	50	1
2972184	83254961	Character Holder PTEF 9.5-28	9,5	28	40	50	1
2972185	83254955	Character Holder PTEF 9.5-35	9,5	35	47	500	1
2972186	83254969	Character Holder PTEF 9.5-35	9,5	35	47	1000	1
2972156	83254963	Character Holder PTEF 9.5-35	9,5	35	47	50	1
2989407	83254962	Character Holder PTEF 9.5-38	9,5	38	50	50	1
2972187	83254964	Character Holder PTEF 9.5-58	9,5	58	70	50	1
2972188	83254967	Character Holder PTEF 9.5-66	9,5	66	78	50	1
2989408	83254965	Character Holder PTEF 9.5-70	9,5	70	82	50	1
2940476	83254968	Character Holder PTEF 9.5-85	9,5	85	97	50	1
2972189	83254966	Character Holder PTEF 9.5-105	9,5	105	117	50	1
2972190	83280006	Character Holder PTEF 12-18	12	18	30	50	1
2972191	83254976	Character Holder PTEF 12-28	12	28	40	50	1
2972192	83254977	Character Holder PTEF 12-38	12	38	50	50	1
2972193	83254979	Character Holder PTEF 12-50	12	50	62	50	1
2972194	83254978	Character Holder PTEF 12-58	12	58	70	50	1
2940475	83254981	Character Holder PTEF 12-85	12	85	97	50	1
2972196	83254982	Character Holder PTEF 19-50	19	50	62	50	1
2940474	83279759	Character Holder PTEF 9,5-18 with lock button	9,5	18	30	1000	1

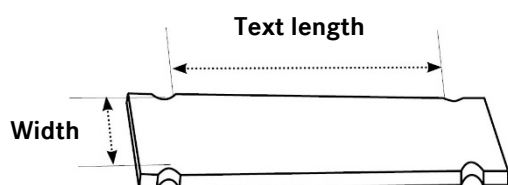

Creator: Fleximark/LR	Document: DB83254970EN FLEXIMARK Character holder PTEF Version: 02	Page 2 of 3
-----------------------	-----------------------------------------------------------------------	-------------

	<b>DATA SHEET</b>	
Valid from: 28-01-2019	<b>FLEXIMARK® character holders PTEF</b>	

### Related products

FLEXIMARK® Character holders are used together with 3M™ DYMO™ Industrial marking labels (vinyl, polyester, glue-free, nylon) and FLEXIMARK® Marking systems. All of the related products are available in FLEXIMARK® Marking assortment.

Following FLEXIMARK® Marking systems and other marking solutions are recommended for FLEXIMARK® Character holders PTEF:

PTEF Size (mm)	Recommended Marking systems (mm)		
6-18	3M™ DYMO™ Marking label 6		
6-28	3M™ DYMO™ Marking label 6		
6-35	3M™ DYMO™ Marking label 6		FLEXIMARK® Flexilabel 6
6-38	3M™ DYMO™ Marking label 6		
6-58	3M™ DYMO™ Marking label 6		FLEXIMARK® Flexilabel 6
9.5-18	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-28	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-35	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-38	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-58	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-66	3M™ DYMO™ Marking label 9,5		FLEXIMARK® Flexilabel 9,5
9.5-70	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-85	3M™ DYMO™ Marking label 9,5	FLEXIMARK® MINI Marking system	FLEXIMARK® Flexilabel 9,5
9.5-105	3M™ DYMO™ Marking label 9,5		FLEXIMARK® Flexilabel 9,5
12-18	3M™ DYMO™ Marking label 12		
12-28	3M™ DYMO™ Marking label 12		
12-38	3M™ DYMO™ Marking label 12		FLEXIMARK® Flexilabel 12
12-50	3M™ DYMO™ Marking label 12		FLEXIMARK® Flexilabel 12
12-58	3M™ DYMO™ Marking label 12		
12-85	3M™ DYMO™ Marking label 12		
19-50	3M™ DYMO™ Marking label 19		FLEXIMARK® Flexilabel 19

### Note:

Pictures are not to scale and do not represent detailed images of each product.

Creator: Fleximark/LR	Document: DB83254970EN FLEXIMARK Character holder PTEF Version: 02	Page 3 of 3
-----------------------	-----------------------------------------------------------------------	-------------