
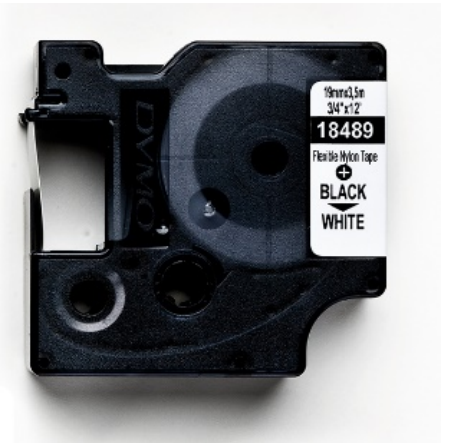


	<b>DATA SHEET</b>	
Valid from: 2019-11-08	<b>DYMO® Shrink tube</b>	

Specially developed for tough industrial environment.  
 Polyolefin solution containing no adhesive.  
 Permanent for marking and protection of cables and wires.  
 Fire protected and with shrinkage factor 3:1.  
 The color combinations are adapted to different Control Standards  
 (ANSI Z535, ISO3864, ANSI A 13.1, ISO7010, ANSI606-B).



**XTL tapes**



**Rhino tapes**

**Technical data**

Material:	Polyolefin
Shrink ratio:	3:1
Operating temperature:	-18°C to +135°C
Flame retardant:	UL 294
Colour:	White, Yellow


**Other product data:**

ETIM Classification:	EC001288
----------------------	----------

**Advantages:**

The shrink tube is flame retardant with a shrinkage factor of 3:1.  
 The shrink tube is available in sizes 6, 9, 12, 19 and 24 mm and in different colors.  
 The colour combinations are adapted to different control standards, such as: ANSI Z535, ISO38641, ANSI A3.1, S070010, ANSI606-B.

Creator: Fleximark/LR	Document: DB83259470EN DYMO shrink tube Version: 00	Page 1 of 2
-----------------------	--	-------------

	<b>DATA SHEET</b>	
Valid from: 2019-11-08	<b>DYMO® Shrink tube</b>	

**Product data:**

**Shrink tube, DYMO® Rhino**

E-number	Lapp article no.	Article designation	Width mm	Length mm	Colour	Text	PU
2972140	83259470	Krympslang 6mm PLHS-WH-6	6	1,5	White	Black	1
2972141	83259471	Krympslang 6mm PLHS-YE-6	6	1,5	Yellow	Black	1
2972142	83259474	Krympslang 9mm PLHS-WH-9	9	1,5	White	Black	1
2972143	83259475	Krympslang 9mm PLHS-YE-9	9	1,5	Yellow	Black	1
2972144	83259478	Krympslang 12mm PLHS-WH-12	12	1,5	White	Black	1
2972145	83259479	Krympslang 12mm PLHS-YE-12	12	1,5	Yellow	Black	1
2972146	83259482	Krympslang 19mm PLHS-WH-19	19	1,5	White	Black	1
2972147	83259483	Krympslang 19mm PLHS-YE-19	19	1,5	Yellow	Black	1

**Shrink tube, DYMO® XTL**

Industrial shrink tube labelling. 3:1 shrinkage ratio improves cable fit. UL969 Approved. Supplied on a roller with 2.7 m shrink tubing.

E-number	Lapp article no.	Article designation	Width mm	Length m	Colour	Text	PU
1635464	83257214	DYMO XTL Krympslang 6BK/WH	6	2,7	White	Black	1
1635465	83257215	DYMO XTL Krympslang 12BK/WH	12	2,7	White	Black	1
1635466	83257216	DYMO XTL Krympslang 24BK/WH	24	2,7	White	Black	1
1635467	83257217	DYMO XTL Krympslang 54BK/WH	54	2,7	White	Black	1

**Shrink tube pre-cut, DYMO® XTL**

Industrial shrink tube labelling. 3:1 shrinkage ratio improves cable fit. UL969 Approved.

E-number	Lapp article no.	Article designation	Width mm	Length mm	Colour	Text	PU
1635366	83257132	DYMO XTL Krympslang 6x34WH	6	34	White	Black	1
1635367	83257133	DYMO XTL Krympslang 12x34WH	12	34	White	Black	1
1635369	83257134	DYMO XTL Krympslang 24x34WH	24	34	White	Black	1
1635370	83257135	DYMO XTL Krympslang 54x34WH	54	34	White	Black	1
1635371	83257136	DYMO XTL Krympslang 6x47WH	6	47	White	Black	1
1635384	83257137	DYMO XTL Krympslang 12x47WH	12	47	White	Black	1
1635385	83257138	DYMO XTL Krympslang 24x47WH	24	47	White	Black	1
1635386	83257139	DYMO XTL Krympslang 54x47WH	54	47	White	Black	1

**Note:**

Pictures are not to scale and do not represent detailed images of each product.

Creator: Fleximark/LR	Document: DB83259470EN DYMO shrink tube Version: 00	Page 2 of 2
-----------------------	--	-------------