
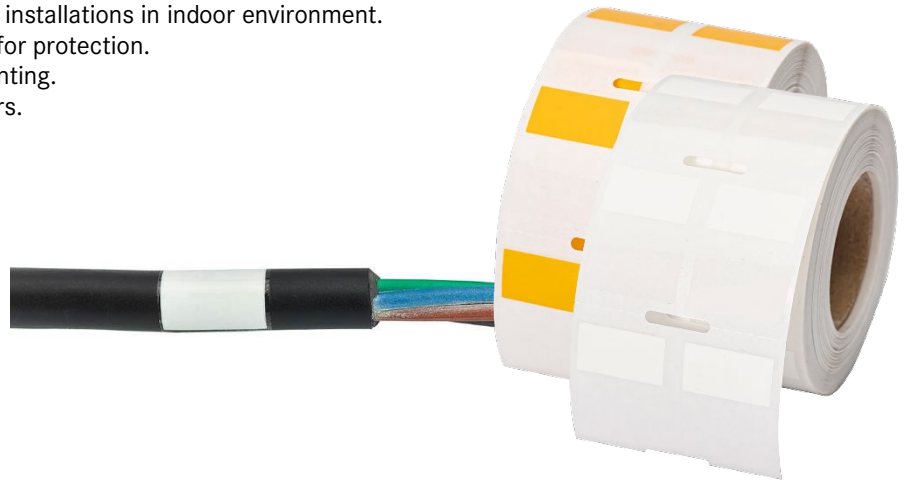


	DATA SHEET	
Valid from: 06-12-2018	FLEXIMARK® Wrapping label TCK	

High quality wrapping label for cables and pipes.
 Used for industrial, electrical and telecom installations in indoor environment.
 Print area with laminated transparent foil for protection.
 Delivered on a roll for thermal transfer printing.
 Different sizes for different cable diameters.
 UV-resistant/stable.



Technical data polyester:

Material:	Polyester, halogen-free
Adhesive:	Permanent acrylic
Core:	38mm (standard)
Colour:	White, Yellow
Temperature range:	-40°C to 125°C
Applying temperature:	min 10°C
Recommended storage:	21°C and 50% RH, <two years

Technical data vinyl:

Material:	Vinyl
Adhesive:	Permanent acrylic
Core:	38mm (standard)
Colour:	White, Yellow
Temperature range:	-40°C to 80°C
Applying temperature:	min 10°C
Recommended storage:	21°C and 50% RH, <two years
Expected exterior life:	Five years


Other product data:

ETIM Classification:	EC001288 Labelling material
Country of origin:	SE

Advantages:

Print your own durable marking when you need it.
 No cable ties are necessary for mounting.
 Durable marking with a laminated protection over the text.
 Halogen free (*Polyester) material with UV-resistance.
 Text with long term durability thanks to thermal transfer printing and high quality materials.
 Thermal transfer printing method increases smudge, scratch resistance and resistance to oils and chemicals.


Creator: Fleximark/LR	Document: DB83259874EN FLEXIMARK Wrapping label TCK Version: 03	Page 1 of 4
-----------------------	--	-------------

	DATA SHEET	
Valid from: 06-12-2018	FLEXIMARK® Wrapping label TCK	

Print area



Laminated foil

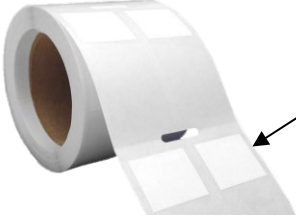


Amount of labels in a row

Delivery:

Wrapping label is delivered on a roll for printing with a thermal transfer printer.

Mounting:

FLEXIMARK® Wrapping label TCK is mounted directly on the cable, by wrapping the label around the cable with printing area first. At the end the transparent foil will cover the printing and protect the print against different strains.

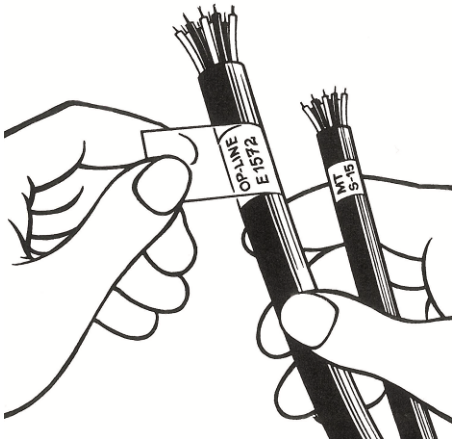

Creator: Fleximark/LR	Document: DB83259874EN FLEXIMARK Wrapping label TCK Version: 03	Page 2 of 4
-----------------------	--	-------------

DATA SHEET



Valid from:
06-12-2018

FLEXIMARK® Wrapping label TCK


Product data:

Polyester

E-nr	LAPP Part no.	Article designation	Colour	For outer ø (mm)	Print area (mm)	Total Size (mm)	Content (unit)	Labels in a row	PU
2942040	83259874	FLEXIMARK LABEL TCK 32 25x33,5 WH	White	7	23x12.7	25x33,5	2400	2	1
2942041	83259875	FLEXIMARK LABEL TCK 35 25x55 WH	White	12	23x19	25x55	1200	2	1
2942042	83259876	FLEXIMARK LABEL TCK 40 25x94 WH	White	21	23x25.4	25x94	600	2	1
2942043	83259877	FLEXIMARK LABEL TCK 45 25x142,5 WH	White	36	23x25.4	25x142,5	600	2	1
2942054	83259890	FLEXIMARK LABEL TCK 48 34x93 WH	White	21	32x25	34x93	600	2	1
2942044	83259878	FLEXIMARK LABEL TCK 60 50x56 WH	White	12	48x19	50x56	600	2	1
2942045	83259879	FLEXIMARK LABEL TCK 65 50x94 WH	White	21	48x25.4	50x94	600	2	1
2942046	83259881	FLEXIMARK LABEL TCK 70 50x142,5 WH	White	36	48x25.4	50x142,5	600	2	1
2942047	83259882	FLEXIMARK LABEL TCK 32 25x33,5 YE	Yellow	7	23x12.7	25x33,5	1200	2	1
2942048	83259883	FLEXIMARK LABEL TCK 35 25x55 YE	Yellow	12	23x19	25x55	1200	2	1
2942049	83259884	FLEXIMARK LABEL TCK 40 25x94 YE	Yellow	21	23x25.4	25x94	600	2	1
2942050	83259885	FLEXIMARK LABEL TCK 45 25x142,5 YE	Yellow	36	23x25.4	25x142,5	600	2	1
2942055	83259889	FLEXIMARK LABEL TCK 48 34x93 YE	Yellow	21	32x25	34x93	600	2	1
2942051	83259886	FLEXIMARK LABEL TCK 60 50x56 YE	Yellow	12	48x19	50x56	600	2	1
2942052	83259887	FLEXIMARK LABEL TCK 65 50x94 YE	Yellow	21	48x25.4	50x94	600	2	1
2942053	83259888	FLEXIMARK LABEL TCK 70 50x142,5 YE	Yellow	36	48x25.4	50x142,5	600	2	1

Vinyl

	83259810	FLEXIMARK TCK 20 Vinyl 13x20 WH	White	4	11x9	13x20	2400	4	1
	83259811	FLEXIMARK TCK 32 Vinyl 25x33.5 WH	White	7	23x12.7	25x33,5	1200	2	1
	83259812	FLEXIMARK TCK 35 Vinyl 25x55 WH	White	12	23x19	25x55	1200	2	1
	83259813	FLEXIMARK TCK 40 Vinyl 25x94 WH	White	21	23x25.4	25x94	600	2	1
	83259814	FLEXIMARK TCK 45 Vinyl 25x142.5 WH	White	36	23x25.4	25x142,5	600	2	1
	83259815	FLEXIMARK TCK 48 Vinyl 34x93 WH	White	21	32x25	34x93	600	2	1
	83259816	FLEXIMARK TCK 60 Vinyl 50x56 WH	White	12	48x19	50x56	600	2	1
	83259817	FLEXIMARK TCK 65 Vinyl 50x94WH	White	21	48x25.4	50x94	600	2	1
	83259818	FLEXIMARK TCK 70 Vinyl 50x142.5 WH	White	36	48x25.4	50x142,5	600	2	1
	83259819	FLEXIMARK TCK 20 Vinyl 13x20 YE	Yellow	4	11x9	13x20	2400	4	1
	83259820	FLEXIMARK TCK 32 Vinyl 25x33.5 YE	Yellow	7	23x12.7	25x33,5	1200	2	1
	83259821	FLEXIMARK TCK 35 Vinyl 25x55 YE	Yellow	12	23x19	25x55	1200	2	1
	83259822	FLEXIMARK TCK 40 Vinyl 25x94 YE	Yellow	21	23x25.4	25x94	600	2	1
	83259823	FLEXIMARK TCK 45 Vinyl 25x142.5 YE	Yellow	36	23x25.4	25x142,5	600	2	1
	83259824	FLEXIMARK TCK 48 Vinyl 34x93 YE	Yellow	21	32x25	34x93	600	2	1
	83259825	FLEXIMARK TCK 60 Vinyl 50x56 YE	Yellow	12	48x19	50x56	600	2	1
	83259826	FLEXIMARK TCK 65 Vinyl 50x94YE	Yellow	21	48x25.4	50x94	600	2	1
	83259827	FLEXIMARK TCK 70 Vinyl 50x142.5 YE	Yellow	36	48x25.4	50x142,5	600	2	1

	DATA SHEET	
Valid from: 06-12-2018	FLEXIMARK® Wrapping label TCK	

Related products:

FLEXIMARK® Wrapping label TCK is printed with CAB thermal transfer printers (available in our assortment). To make the printing process more efficient, the usage of FLEXIMARK® Software, label software for printing marking systems, is recommended.

It is important to use the correct ribbon for printing your marking. Recommended ribbon for FLEXIMARK® Wrapping label TCK and FLEXIMARK® Wrapping label TCK Vinyl is Ribbon R71, article number 83259609.



Note:

Pictures are not to scale and do not represent detailed images of each product.

Creator: Fleximark/LR	Document: DB83259874EN FLEXIMARK Wrapping label TCK Version: 03	Page 4 of 4
-----------------------	--	-------------