


	DATA SHEET	
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

For wire and cable identification.

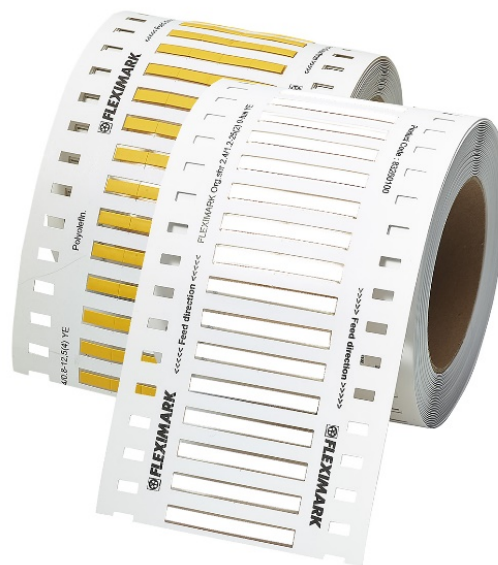

Technical data, Halogen Free:

Material:

Shrink ratio:

Operating temperature:

Shrink temperature:

Mark Permanence:

Print Resistance to solvents:

Industry Standards:

Recommended black ribbon:

Colour (other on request):

Recommended storage:

Applications:

Crosslinked Polyolefin

2:1

-55°C to +105°C (-67°F to 221°F)

≥90° (194°F)

SAE AS-5942 LUL 3349

MIL-STD-202G Test method 215K

EN45545-2 Class HL3 R22-23

NF F 16-101

London Underground

1-085 A3

BOEING BSS 7239

UNI CEI 11170-3 (LR4)

DIN 5510-2 BS6853: 1999 vehicle category 1

83260206 (Ribbon FTI-X 60-300 BK)

White, Yellow

Cool and dry, +10°C to +25°C and 45-55% RH

Specific developed to be used in Rail, Aerospace, Marine, industrial marking, insulation, wire bundling and mechanical protection.

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 1 of 8
-----------------------	---	-------------

	DATA SHEET	
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

Technical data, Military Grade Self Extinguishing:

Material:	Crosslinked Polyolefin
Shrink ratio:	3:1
Operating temperature:	-55°C to +135°C (-67°F to 275°F)
Shrink temperature:	≥90° (194°F)
Mark Permanence:	SAE AS-5942
Print Resistance to solvents:	MIL-STD-202G Test method 215K
Fire Propagation:	ASTM D2671 Procedure B
Toxicity:	N-A
Airbus Standard:	NSA937201 Table 7
UL224 125°C:	Certificate E228117
CSA-C22.2:	No. 198.1-06
Material Performance:	AMS SAE DTL 23053/5 Class 1
Colour (other on request):	White, Yellow
Recommended storage:	Cool and dry, +10°C to +25°C and 45-55% RH
Applications:	Specific developed to be used in Aerospace, Military, Industrial, energy marking, insulation, wire bundling and mechanical protection.

Technical data, Diesel resistant, Self Extinguishing:

Material:	Crosslinked Polyolefin
Shrink ratio:	3:1
Operating temperature:	-40°C to +125°C (-40°F to 193°F)
Shrink temperature:	>90°C (130°F)
Mark Permanence:	SAE AS-5942 Superceeds SAE AS 81531:1998 Section 4.6.2 NF F00-608 fluid test cat A & H
Industry Standards:	NFF F-00-608 cat. A & H MIL-DTL-23053/6 class 1
Flammability	AMS-DTL-23053 1999 4.6.14 ASTM D2671-09 Section 6874 Procedure B and AMSDTL-23053/6:1999 UL224
Colour (other on request):	White, Yellow
Recommended storage:	Cool and dry, +10°C to +25°C and 45-55% RH
Applications:	Specific developed to be used in Rail, Defence, Aerospace, cable harnesses, Industrial marking, insulation, wire bundling and mechanical protection.

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 2 of 8
-----------------------	---	-------------

	DATA SHEET	
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

Mounting:

FLEXIMARK® Organized shrink tube is mounted direct on cable or wire, when needed along with the heating tool.

Other product data:

ETIM Classification:

EC001288

Advantages:

Print your own marking when you need it.

Made of the flexible and self-extinguishing polyolefin tube.

Text with long term durability thanks to thermotransfer printing.

The thermal transfer printing method increases resistance to abrasion, oil and chemicals.

Many different sizes for different wires, cables and parts.

The label roll gives a better overview of the printout.

Delivery:

On roll suitable for thermal transfer printing.

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 3 of 8
-----------------------	---	-------------

DATA SHEET		
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

Product data Halogen Free organized shrink tube:

E-nr.	LAPP Part no.	Article designation	Colour	Size before /after shrink (mm)	Length (mm)	Amount of labels in a row	Content (unit)	PU
	83260219	Org. Shrink tube 2.4/1.2-12.5(4) 0-hal WH	White	2.4/1.2	12,5	4	4000	1
	83260220	Org. Shrink tube 3.2/1.6-12.5(4) 0-hal WH	White	3.2/1.6	12,5	4	4000	1
	83260221	Org. Shrink tube 4.8/2.4-12.5(4) 0-hal WH	White	4.8/2.4	12,5	4	4000	1
	83260222	Org. Shrink tube 2.4/1.2-16.6(3) 0-hal WH	White	2.4/1.2	16,6	3	3000	1
	83260223	Org. Shrink tube 3.2/1.6-16.6(3) 0-hal WH	White	3.2/1.6	16,6	3	3000	1
	83260224	Org. Shrink tube 4.8/2.4-16.6(3) 0-hal WH	White	4.8/2.4	16,6	3	3000	1
2940958	83260225	Org. Shrink tube 2.4/1.2-12.5(4) 0-hal YE	Yellow	2.4/1.2	12,5	4	4000	1
2940959	83260226	Org. Shrink tube 3.2/1.6-12.5(4) 0-hal YE	Yellow	3.2/1.6	12,5	4	4000	1
2940983	83260227	Org. Shrink tube 4.8/2.4-12.5(4) 0-hal YE	Yellow	4.8/2.4	12,5	4	4000	1
2940984	83260228	Org. Shrink tube 2.4/1.2-16.6(3) 0-hal YE	Yellow	2.4/1.2	16,6	3	3000	1
2940985	83260229	Org. Shrink tube 3.2/1.6-16.6(3) 0-hal YE	Yellow	3.2/1.6	16,6	3	3000	1
2940986	83260230	Org. Shrink tube 4.8/2.4-16.6(3) 0-hal YE	Yellow	4.8/2.4	16,6	3	3000	1
	83260245	Org.shr 4.0/2.0-50(1) 0-hal WH	White	4.0/2.0	50	1	1000	1
	83260246	Org.shr 4.0/2.0x25(2) 0-hal WH	White	4.0/2.0	25	2	2000	1
	83260247	Org.s 4.0/2.0-16.6(3) 0-hal WH	White	4.0/2.0	16	3	3000	1
	83260248	Org.s 4.0/2.0x12.5(4) 0-hal WH	White	4.0/2.0	12,5	4	4000	1
	83260249	Org.shr 4.0/2.0-50(1) 0-hal YE	Yellow	4.0/2.0	50	1	1000	1
	83260250	Org.shr 4.0/2.0x25(2) 0-hal YE	Yellow	4.0/2.0	25	2	2000	1
	83260251	Org.s 4.0/2.0-16.6(3) 0-hal YE	Yellow	4.0/2.0	16	3	3000	1
	83260252	Org.s 4.0/2.0x12.5(4) 0-hal YE	Yellow	4.0/2.0	12,5	4	4000	1
	83260255	O.shr 3.2/1.6-12.5(4) 0-hal GY	Grey	3.2/1.6	12,5	4	4000	1
	83260256	O.shr 3.2/1.6-16.6(3) 0-hal GY	Grey	3.2/1.6	16,6	3	3000	1
	83260257	O.shr 4.8/2.4-12.5(4) 0-hal GY	Grey	4.8/2.4	12,5	4	4000	1
	83260278	Org.shr 9.5/4.8-16.6(3) 0-hal YE	Yellow	9.5/4.8	16,6	3	1500	1
	83260279	Org.shr 9.5/4.8-16.6(3) 0-hal WH	White	9.5/4.8	16,6	3	1500	1
	83260280	Org.shr 4.8/2.4-16.6(3) 0-hal GN	Green	4.8/2.4	16,6	3	3000	1
	83260281	Org.shr 9.5/4.8-16.6(3) 0-hal GN	Green	9.5/4.8	16,6	3	1500	1
	83260282	Org.shr 4.8/2.4-16.6(3) 0-hal BU	Blue	4.8/2.4	16,6	3	3000	1
	83260283	Org.shr 9.5/4.8-16.6(3) 0-hal BU	Blue	9.5/4.8	16,6	3	1500	1
	83260284	Org.shr 4.8/2.4-16.6(3) 0-hal RD	Red	4.8/2.4	16,6	3	3000	1
	83260285	Org.shr 9.5/4.8-16.6(3) 0-hal RD	Red	9.5/4.8	16,6	3	1500	1
	83260286	Org.shr 4.8/2.4-16.6(3) 0-hal GY	Grey	4.8/2.4	16,6	3	3000	1
	83260287	Org.shr 9.5/4.8-16.6(3) 0-hal GY	Grey	9.5/4.8	16,6	3	1500	1
	83260288	Org.shr 4.8/2.4-16.6(3) 0-hal OG	Orange	4.8/2.4	16,6	3	3000	1
	83260289	Org.shr 9.5/4.8-16.6(3) 0-hal OG	Orange	9.5/4.8	16,6	3	1500	1
	83260300	O.shr 9.5/4.8-12.5(4) 0-hal YE	Yellow	9.5/4.8	12,5	4	2000	1
	83260301	O.shr 9.5/4.8-12.5(4) 0-hal WH	White	9.5/4.8	12,5	4	2000	1
	83260052	Org. Shrink tube 2.4/1.2x50(1) 0-hal WH	White	2.4/1.2	50	1	1000	1
	83260053	Org. Shrink tube 3.2/1.6x50(1) 0-hal WH	White	3.2/1.6	50	1	1000	1
	83260054	Org. Shrink tube 4.8/2.4x50(1) 0-hal WH	White	4.8/2.4	50	1	1000	1
	83260055	Org. Shrink tube 6.4/3.2x50(1) 0-hal WH	White	6.4/3.2	50	1	1000	1
	83260056	Org. Shrink tube 9.5/4.8x50(1) 0-hal WH	White	9.5/4.8	50	1	500	1
	83260057	Org. Shrink tube 12.7/6.4x50(1) 0-hal WH	White	12.7/6.4	50	1	500	1
	83260058	Org. Shrink tube 19.1/9.5x50(1) 0-hal WH	White	19.1/9.5	50	1	500	1
	83260059	Org. Shrink tube 25.4/12.7x50(1) 0-hal WH	White	25.4/12.7	50	1	300	1
	83260060	Org. Shrink tube 38.1/19.1x50(1) 0-hal WH	White	38.1/19.1	50	1	100	1
	83260061	Org. Shrink tube 50.8/25.4x50(1) 0-hal WH	White	50.8/25.4	50	1	100	1
2940696	83260062	Org. Shrink tube 2.4/1.2x38(1) 0-hal WH	White	2.4/1.2	38	1	1000	1
2940697	83260063	Org. Shrink tube 3.2/1.6x38(1) 0-hal WH	White	3.2/1.6	38	1	1000	1
2940698	83260064	Org. Shrink tube 4.8/2.4x38(1) 0-hal WH	White	4.8/2.4	38	1	1000	1
2940699	83260065	Org. Shrink tube 6.4/3.2x38(1) 0-hal WH	White	6.4/3.2	38	1	1000	1
2940587	83260066	Org.shrink tube 9.5/4.8x38(1) 0-hal WH	White	9.5/4.8	38	1	500	1
2940746	83260067	Org.shrink tube 12.7/6.4x38(1) 0-hal WH	White	12.7/6.4	38	1	500	1
2940747	83260068	Org.shrink tube 19.1/9.5x38(1) 0-hal WH	White	19.1/9.5	38	1	500	1
2940748	83260069	Org.shrink tube 25.4/12.7x38(1) 0-hal WH	White	25.4/12.7	38	1	300	1
2940749	83260070	Org.shrink tube 38.1/19.1x38(1) 0-hal WH	White	38.1/19.1	38	1	100	1
	83260071	Org.shrink tube 50.8/25.4x38(1) 0-hal WH	White	50.8/25.4	38	1	100	1
2940797	83260072	Org.shrink tube 2.4/1.2x25(2) 0-hal WH	White	2.4/1.2	25	2	2000	1
2940798	83260073	Org.shrink tube 3.2/1.6x25(2) 0-hal WH	White	3.2/1.6	25	2	2000	1
2940799	83260074	Org.shrink tube 4.8/2.4x25(2) 0-hal WH	White	4.8/2.4	25	2	2000	1
2940800	83260075	Org.shrink tube 6.4/3.2x25(2) 0-hal WH	White	6.4/3.2	25	2	2000	1
2940816	83260076	Org.shrink tube 9.5/4.8x25(2) 0-hal WH	White	9.5/4.8	25	2	1000	1
2940817	83260077	Org.shrink tube 12.7/6.4x25(2) 0-hal WH	White	12.7/6.4	25	2	1000	1
2940818	83260078	Org.shrink tube 19.1/9.5x25(2) 0-hal WH	White	19.1/9.5	25	2	1000	1
2940819	83260079	Org.shrink tube 25.4/12.7x25(2) 0-hal WH	White	25.4/12.7	25	2	600	1
2940856	83260080	Org.shrink tube 2.4/1.2x50(1) 0-hal YE	Yellow	2.4/1.2	50	1	1000	1
2940857	83260081	Org.shrink tube 3.2/1.6x50(1) 0-hal YE	Yellow	3.2/1.6	50	1	1000	1
2940858	83260082	Org.shrink tube 4.8/2.4x50(1) 0-hal YE	Yellow	4.8/2.4	50	1	1000	1
2940859	83260083	Org.shrink tube 6.4/3.2x50(1) 0-hal YE	Yellow	6.4/3.2	50	1	1000	1

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 4 of 8
-----------------------	---	-------------

Valid from: 06.12.2018		DATA SHEET	
		FLEXIMARK® Organized shrink tube	

2940860	83260084	Org.shrink tube 9.5/4.8x50(1) 0-hal YE	Yellow	9.5/4.8	50	1	500	1
2940869	83260085	Org.shrink tube 12.7/6.4x50(1)0-hal YE	Yellow	12.7/6.4	50	1	500	1
2940870	83260086	Org.shrink tube 19.1/9.5x50(1)0-hal YE	Yellow	19.1/9.5	50	1	500	1
2940878	83260087	Org.shrink tube 25.4/12.7x50(1)0-halYE	Yellow	25.4/12.7	50	1	300	1
2940879	83260088	Org.shrink tube 38.1/19.1x50(1)0-halYE	Yellow	38.1/19.1	50	1	100	1
2940880	83260089	Org.shrink tube 50.8/25.4x50(1)0-halYE	Yellow	50.8/25.4	50	1	100	1
2940883	83260090	Org.shrink tube 2.4/1.2x38(1) 0-hal YE	Yellow	2.4/1.2	38	1	1000	1
2940884	83260091	Org.shrink tube 3.2/1.6x38(1) 0-hal YE	Yellow	3.2/1.6	38	1	1000	1
2940885	83260092	Org.shrink tube 4.8/2.4x38(1) 0-hal YE	Yellow	4.8/2.4	38	1	1000	1
2940886	83260093	Org.shrink tube 6.4/3.2x38(1) 0-hal YE	Yellow	6.4/3.2	38	1	1000	1
2940887	83260094	Org.shrink tube 9.5/4.8x38(1) 0-hal YE	Yellow	9.5/4.8	38	1	500	1
2940888	83260095	Org.shrink tube 12.7/6.4x38(1)0-hal YE	Yellow	12.7/6.4	38	1	500	1
2940889	83260096	Org.shrink tube 19.1/9.5x38(1)0-hal YE	Yellow	19.1/9.5	38	1	500	1
2940890	83260097	Org.shrink tube 25.4/12.7x38(1)0-halYE	Yellow	25.4/12.7	38	1	300	1
2940893	83260098	Org.shrink tube 38.1/19.1x38(1)0-halYE	Yellow	38.1/19.1	38	1	100	1
	83260099	Org.shrink tube 50.8/25.4x38(1)0-halYE	Yellow	50.8/25.4	38	1	100	1
2940897	83260100	Org.shrink tube 2.4/1.2x25(2) 0-hal YE	Yellow	2.4/1.2	25	2	2000	1
2940898	83260101	Org.shrink tube 3.2/1.6x25(2) 0-hal YE	Yellow	3.2/1.6	25	2	2000	1
2940904	83260102	Org.shrink tube 4.8/2.4x25(2) 0-hal YE	Yellow	4.8/2.4	25	2	2000	1
2940905	83260103	Org.shrink tube 6.4/3.2x25(2) 0-hal YE	Yellow	6.4/3.2	25	2	2000	1
2940906	83260104	Org.shrink tube 9.5/4.8x25(2) 0-hal YE	Yellow	9.5/4.8	25	2	1000	1
2940907	83260105	Org.shrink tube 12.7/6.4x25(2)0-hal YE	Yellow	12.7/6.4	25	2	1000	1
2940908	83260106	Org.shrink tube 19.1/9.5x25(2)0-hal YE	Yellow	19.1/9.5	25	2	1000	1
2940909	83260107	Org.shrink tube 25.4/12.7x25(2)0-halYE	Yellow	25.4/12.7	25	2	600	1

Available colours

Grey 	White 	Red 	Blue 	Green 	Yellow 	Orange 
--	---	---	--	---	--	--

Product data Diesel resistant, Self Extinguishing:

LAPP Part no.	Article designation	Colour	Size before /after shrink (mm)	Length (mm)	Amount of labels in a row	Content (unit)	PU
83260108	Org.shrink tube 2.4/0.8x50(1) DR WT	White	2.4/0.8	50	1	1000	1
83260109	Org.shrink tube 3.2/1.1x50(1) DR WT	White	3.2/1.1	50	1	1000	1
83260110	Org.shrink tube 4.8/1.6x50(1) DR WT	White	4.8/1.6	50	1	1000	1
83260111	Org.shrink tube 6.4/2.1x50(1) DR WT	White	6.4/2.1	50	1	1000	1
83260112	Org.shrink tube 9.5/3.2x50(1) DR WT	White	9.5/3.2	50	1	500	1
83260113	Org.shrink tube 12.7/4.2x50(1) DR WT	White	12.7/4.2	50	1	500	1
83260114	Org.shrink tube 19.1/6.4x50(1) DR WT	White	19.1/6.4	50	1	500	1
83260115	Org.shrink tube 25.4/9.5x50(1)DRWT	White	25.4/9.5	50	1	300	1
83260116	Org.shrink tube 38.1/12.7x50(1)DRWT	White	38.1/12.7	50	1	100	1
83260117	Org.shrink tube 38.1/12.7x75(1)DRWT	White	38.1/12.7	75	1	100	1
83260118	Org.shrink tube 2.4/0.8x38(1) DR WT	White	2.4/0.8	38	1	1000	1
83260119	Org.shrink tube 3.2/1.1x38(1) DR WT	White	3.2/1.1	38	1	1000	1
83260120	Org.shrink tube 4.8/1.6x38(1) DR WT	White	4.8/1.6	38	1	1000	1
83260121	Org.shrink tube 6.4/2.1x38(1) DR WT	White	6.4/2.1	38	1	1000	1
83260122	Org.shrink tube 9.5/3.2x38(1) DR WT	White	9.5/3.2	38	1	500	1
83260123	Org.shrink tube 12.7/4.2x38(1) DR WT	White	12.7/4.2	38	1	500	1
83260124	Org.shrink tube 19.1/6.4x38(1) DR WT	White	19.1/6.4	38	1	500	1
83260125	Org.shrink tube 25.4/9.5x38(1) DR WT	White	25.4/9.5	38	1	300	1
83260126	Org.shrink tube 38.1/12.7x38(1)DR WT	White	38.1/12.7	38	1	100	1
83260127	Org.shrink tube 2.4/0.8x25(2) DR WT	White	2.4/0.8	25	2	2000	1
83260128	Org.shrink tube 3.2/1.1x25(2) DR WT	White	3.2/1.1	25	2	2000	1
83260129	Org.shrink tube 4.8/1.6x25(2) DR WT	White	4.8/1.6	25	2	2000	1
83260130	Org.shrink tube 6.4/2.1x25(2) DR WT	White	6.4/2.1	25	2	2000	1
83260131	Org.shrink tube 9.5/3.2x25(2) DR WT	White	9.5/3.2	25	2	1000	1
83260132	Org.shrink tube 12.7/4.2x25(2) DR WT	White	12.7/4.2	25	2	1000	1
83260133	Org.shrink tube 19.1/6.4x25(2) DR WT	White	19.1/6.4	25	2	1000	1
83260134	Org.shrink tube 25.4/9.5x25(2) DR WT	White	25.4/9.5	25	2	600	1
83260135	Org.shrink tube 38.1/12.7x25(2)DR WT	White	38.1/12.7	25	2	200	1
83260136	Org.shrink tube 2.4/0.8x50(1) DR YE	Yellow	2.4/0.8	50	1	1000	1
83260137	Org.shrink tube 3.2/1.1x50(1) DR YE	Yellow	3.2/1.1	50	1	1000	1
83260138	Org.shrink tube 4.8/1.6x50(1) DR YE	Yellow	4.8/1.6	50	1	1000	1
83260139	Org.shrink tube 6.4/2.1x50(1) DR YE	Yellow	6.4/2.1	50	1	1000	1
83260140	Org.shrink tube 9.5/3.2x50(1) DR YE	Yellow	9.5/3.2	50	1	500	1
83260141	Org.shrink tube 12.7/4.2x50(1) DR YE	Yellow	12.7/4.2	50	1	500	1
83260142	Org.shrink tube 19.1/6.4x50(1) DR YE	Yellow	19.1/6.4	50	1	500	1
83260143	Org.shrink tube 25.4/9.5x50(1) DR YE	Yellow	25.4/9.5	50	1	300	1
83260144	Org.shrink tube 38.1/12.7x50(1)DR YE	Yellow	38.1/12.7	50	1	100	1
83260145	Org.shrink tube 38.1/12.7x75(1)DR YE	Yellow	38.1/12.7	75	1	100	1
83260146	Org.shrink tube 2.4/0.8x38(1) DR YE	Yellow	2.4/0.8	38	1	1000	1
83260147	Org.shrink tube 3.2/1.1x38(1) DR YE	Yellow	3.2/1.1	38	1	1000	1
83260148	Org.shrink tube 4.8/1.6x38(1) DR YE	Yellow	4.8/1.6	38	1	1000	1
83260149	Org.shrink tube 6.4/2.1x38(1) DR YE	Yellow	6.4/2.1	38	1	1000	1
83260150	Org.shrink tube 9.5/3.2x38(1) DR YE	Yellow	9.5/3.2	38	1	500	1

Creator: Fleximark/LR

Document: DB83260219EN Organized shrink tube
Version: 01

Page 5 of 8

	DATA SHEET	
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

83260151	Org.shrink tube 12.7/4.2x38(1) DR YE	Yellow	12.7/4.2	38	1	500	1
83260152	Org.shrink tube 19.1/6.4x38(1) DR YE	Yellow	19.1/6.4	38	1	500	1
83260153	Org.shrink tube 25.4/9.5x38(1) DR YE	Yellow	25.4/9.5	38	1	300	1
83260154	Org.shrink tube 38.1/12.7x38(1) DR YE	Yellow	38.1/12.7	38	1	100	1
83260155	Org.shrink tube 2.4/0.8x25(2) DR YE	Yellow	2.4/0.8	25	2	2000	1
83260156	Org.shrink tube 3.2/1.1x25(2) DR YE	Yellow	3.2/1.1	25	2	2000	1
83260157	Org.shrink tube 4.8/1.6x25(2) DR YE	Yellow	4.8/1.6	25	2	2000	1
83260158	Org.shrink tube 6.4/2.1x25(2) DR YE	Yellow	6.4/2.1	25	2	2000	1
83260159	Org.shrink tube 9.5/3.2x25(2) DR YE	Yellow	9.5/3.2	25	2	1000	1
83260160	Org.shrink tube 12.7/4.2x25(2) DR YE	Yellow	12.7/4.2	25	2	1000	1
83260161	Org.shrink tube 19.1/6.4x25(2) DR YE	Yellow	19.1/6.4	25	2	1000	1
83260162	Org.shrink tube 25.4/9.5x25(2) DR YE	Yellow	25.4/9.5	25	2	600	1
83260163	Org.shrink tube 38.1/12.7x25(2) DR YE	Yellow	38.1/12.7	25	2	200	1

Product data Military Grade Self Extinguishing:

LAPP Part no.	Article designation	Colour	Size before /after shrink (mm)	Length (mm)	Amount of labels in a row	Content (unit)	PU
83260207	Org. Shrink tube. 2.4/0.8-12.5(4) WH	White	2.4/0.8	12,5	4	4000	1
83260208	Org. Shrink tube. 3.2/1.0-12.5(4) WH	White	3.2/1.0	12,5	4	4000	1
83260209	Org. Shrink tube. 4.8/1.6-12.5(4) WH	White	4.8/1.6	12,5	4	4000	1
83260210	Org. Shrink tube. 2.4/0.8-16.6(3) WH	White	2.4/0.8	16,6	3	3000	1
83260211	Org. Shrink tube. 3.2/1.0-16.6(3) WH	White	3.2/1.0	16,6	3	3000	1
83260212	Org. Shrink tube. 4.8/1.6-16.6(3) WH	White	4.8/1.6	16,6	3	3000	1
83260213	Org. Shrink tube. 2.4/0.8-12.5(4) YE	Yellow	2.4/0.8	12,5	4	4000	1
83260214	Org. Shrink tube. 3.2/1.0-12.5(4) YE	Yellow	3.2/1.0	12,5	4	4000	1
83260215	Org. Shrink tube. 4.8/1.6-12.5(4) YE	Yellow	4.8/1.6	12,5	4	4000	1
83260216	Org. Shrink tube. 2.4/0.8-16.6(3) YE	Yellow	2.4/0.8	16,6	3	3000	1
83260217	Org. Shrink tube. 3.2/1.0-16.6(3) YE	Yellow	3.2/1.0	16,6	3	3000	1
83260218	Org. Shrink tube. 4.8/1.6-16.6(3) YE	Yellow	4.8/1.6	16,6	3	3000	1
83260000	Org. Shrink tube. 2.4/0.8x50(1) WH	White	2.4/0.8	50	1	1000	1
83260001	Org. Shrink tube. 3.2/1.0x50mm(1) WH	White	3.2/1.0	50	1	1000	1
83260002	Org. Shrink tube. 4.8/1.6x50mm(1) WH	White	4.8/1.6	50	1	1000	1
83260003	Org. Shrink tube. 6.4/2.0x50mm(1) WH	White	6.4/2.0	50	1	1000	1
83260004	Org. Shrink tube. 9.5/3.0x50mm(1) WH	White	9.5/3.0	50	1	500	1
83260005	Org. Shrink tube.12.7/4.0x50mm(1)WH	White	12.7/4.0	50	1	500	1
83260006	Org. Shrink tube.19.0/6.0x50mm(1)WH	White	19.0/6.0	50	1	500	1
83260007	Org. Shrink tube.25.4/8.0x50mm(1)WH	White	25.4/8.0	50	1	300	1
83260008	Org. Shrink tube38.1/12.7x75mm(1)WH	White	38.1/12.7	75	1	100	1
83260009	Org. Shrink tube. 2.4/0.8x38mm(1) WH	White	2.4/0.8	38	1	1000	1
83260010	Org. Shrink tube. 3.2/1.0x38mm(1) WH	White	3.2/1.0	38	1	1000	1
83260011	Org. Shrink tube. 4.8/1.6x38mm(1) WH	White	4.8/1.6	38	1	1000	1
83260012	Org. Shrink tube. 6.4/2.0x38mm(1) WH	White	6.4/2.0	38	1	1000	1
83260013	Org. Shrink tube. 9.5/3.0x38mm(1) WH	White	9.5/3.0	38	1	500	1
83260014	Org. Shrink tube.12.7/4.0x38mm(1)WH	White	12.7/4.0	38	1	500	1
83260015	Org. Shrink tube.19.0/6.0x38mm(1)WH	White	19.0/6.0	38	1	500	1
83260016	Org. Shrink tube.25.4/8.0x38mm(1)WH	White	25.4/8.0	38	1	300	1
83260017	Org. Shrink tube38.1/12.7x38mm(1)WH	White	38.1/12.7	38	1	100	1
83260018	Org. Shrink tube. 2.4/0.8x25mm(2) WH	White	2.4/0.8	25	2	2000	1
83260019	Org. Shrink tube. 3.2/1.0x25mm(2) WH	White	3.2/1.0	25	2	2000	1
83260020	Org. Shrink tube. 4.8/1.6x25mm(2) WH	White	4.8/1.6	25	2	2000	1
83260021	Org. Shrink tube. 6.4/2.0x25mm(2) WH	White	6.4/2.0	25	2	2000	1
83260022	Org. Shrink tube. 9.5/3.0x25mm(2) WH	White	9.5/3.0	25	2	1000	1
83260023	Org. Shrink tube.12.7/4.0x25mm(2)WH	White	12.7/4.0	25	2	1000	1
83260024	Org. Shrink tube.19.0/6.0x25mm(2)WH	White	19.0/6.0	25	2	1000	1
83260025	Org. Shrink tube.25.4/8.0x25mm(2)WH	White	25.4/8.0	25	2	600	1
83260026	Org. Shrink tube. 2.4/0.8x50mm(1) YE	Yellow	2.4/0.8	50	1	1000	1
83260027	Org. Shrink tube. 3.2/1.0x50mm(1) YE	Yellow	3.2/1.0	50	1	1000	1
83260028	Org. Shrink tube. 4.8/1.6x50mm(1) YE	Yellow	4.8/1.6	50	1	1000	1
83260029	Org. Shrink tube. 6.4/2.0x50mm(1) YE	Yellow	6.4/2.0	50	1	1000	1
83260030	Org. Shrink tube. 9.5/3.0x50mm(1) YE	Yellow	9.5/3.0	50	1	500	1
83260031	Org. Shrink tube.12.7/4.0x50mm(1)YE	Yellow	12.7/4.0	50	1	500	1
83260032	Org. Shrink tube.19.0/6.0x50mm(1)YE	Yellow	19.0/6.0	50	1	500	1
83260033	Org. Shrink tube.25.4/8.0x50mm(1)YE	Yellow	25.4/8.0	50	1	300	1
83260034	Org. Shrink tube38.1/12.7x75mm(1)YE	Yellow	38.1/12.7	75	1	100	1
83260035	Org. Shrink tube. 2.4/0.8x38mm(1) YE	Yellow	2.4/0.8	38	1	1000	1
83260036	Org. Shrink tube. 3.2/1.0x38mm(1) YE	Yellow	3.2/1.0	38	1	1000	1
83260037	Org. Shrink tube. 4.8/1.6x38mm(1) YE	Yellow	4.8/1.6	38	1	1000	1
83260038	Org. Shrink tube. 6.4/2.0x38mm(1) YE	Yellow	6.4/2.0	38	1	1000	1
83260039	Org. Shrink tube. 9.5/3.0x38mm(1) YE	Yellow	9.5/3.0	38	1	500	1

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 6 of 8
-----------------------	---	-------------

	DATA SHEET	
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

83260040	Org. Shrink tube. 12.7/4.0x38mm(1)YE	Yellow	12.7/4.0	38	1	500	1
83260041	Org. Shrink tube. 19.0/6.0x38mm(1)YE	Yellow	19.0/6.0	38	1	500	1
83260042	Org. Shrink tube. 25.4/8.0x38mm(1)YE	Yellow	25.4/8.0	38	1	300	1
83260043	Org. Shrink tube. 38.1/12.7x38mm(1)YE	Yellow	38.1/12.7	38	1	100	1
83260044	Org. Shrink tube. 2.4/0.8x25mm(2) YE	Yellow	2.4/0.8	25	2	2000	1
83260045	Org. Shrink tube. 3.2/1.0x25mm(2) YE	Yellow	3.2/1.0	25	2	2000	1
83260046	Org. Shrink tube. 4.8/1.6x25mm(2) YE	Yellow	4.8/1.6	25	2	2000	1
83260047	Org. Shrink tube. 6.4/2.0x25mm(2) YE	Yellow	6.4/2.0	25	2	2000	1
83260048	Org. Shrink tube. 9.5/3.0x25mm(2) YE	Yellow	9.5/3.0	25	2	1000	1
83260049	Org. Shrink tube. 12.7/4.0x25mm(2)YE	Yellow	12.7/4.0	25	2	1000	1
83260050	Org. Shrink tube. 19.0/6.0x25mm(2)YE	Yellow	19.0/6.0	25	2	1000	1
83260051	Org. Shrink tube. 25.4/8.0x25mm(2)YE	Yellow	25.4/8.0	25	2	600	1

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 7 of 8
-----------------------	---	-------------

	DATA SHEET	
Valid from: 06.12.2018	FLEXIMARK® Organized shrink tube	

Related Products:

FLEXIMARK® Organized shrink tube is printed on thermotransfer printers (available in Fleximark's range). To simplify and streamline the printing shrink tubes, printing is recommended using the FLEXIMARK® Software. The software FLEXIMARK®. It is also important to choose the correct ribbon for the correct marking.

We recommend FTI-X 60x300 BK ribbon for printing FLEXIMARK® Organized shrink tube.



Micro-therm heat gun is a wire-less, simple heat gun for field use (available in Fleximark's range). +650°C without flame.

Used for shrinking the FLEXIMARK® Organized shrink tube after mounting.



Note:

Pictures are not to scale and do not represent detailed images of each product.

Creator: Fleximark/LR	Document: DB83260219EN Organized shrink tube Version: 01	Page 8 of 8
-----------------------	---	-------------