


83871388	DATA SHEET	
Valid from: 11.12.2024	UV Cable ties	

UV cable tie is made in polyamide 6.6.
Weather resistant version combining the highest UV resistance with the lowest insertion effort.

This cable tie ensures maximum performance over 3000h under continuous UV ray exposure.

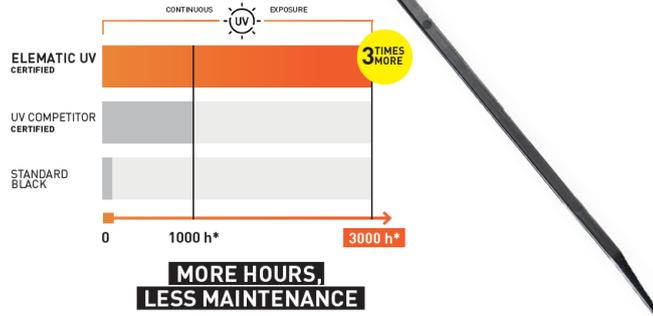

Material:

Strip: Polyamide 6.6 Black

Technical features:

Temperature range: -40°C up to +85°C

Additional features:

Material flammability rating: UL 94-V2
Halogen free
UV-Resistant (tested for 3000 hours SO 4892 - 2 - A method) Equivalent to about 10 years of solar irradiation typical of southern European regions
Heat stabilized

Certifications:

EN45545-2
IEC 62275; DNV Type Approval
Recognized products, product type 11 - File E86244 (Reference standard UL 62275)

Colour: Black

Industries: Photovoltaic systems
Industrial wiring
External installation

Advantages:

Easy to apply.
3 times more UV-resistant than competitors.
Excellent Resistant to: Aromatic solvents, oils, greases and derivatives

Note: *Trade product, no Lapp product.
Pictures are not to scale.

Creator: 11.12.2024/JS Released:	Document: DB83871388EN UV cable ties Version: 00	Page 1 of 3
-------------------------------------	---	-------------

83871388	DATA SHEET	
Valid from: 11.12.2024	UV Cable ties	

Creator: 11.12.2024/JS Released:	Document: DB83871388EN UV cable ties Version: 00	Page 2 of 3
-------------------------------------	---	-------------

83871388	DATA SHEET	
Valid from: 11.12.2024	UV Cable ties	

Product data:

Lapp article no.	Article designation	Size mm	Color	Bundling Ø (mm)	Tensile strength (N)	Quantity /PU	PU
83871388	UV Cable tie 98x2.5	98x2,5	Black	21	80	100	pack
83871389	UV Cable tie 200x2.6	200x2.6	Black	51	80	100	pack
83871390	UV Cable tie 140x3.5	140x3.5	Black	32	130	100	pack
83871391	UV Cable tie 200x3.5	200x3.5	Black	50	130	100	pack
83871392	UV Cable tie 360x4.5	360x4.5	Black	100	220	100	pack
83871393	UV Cable tie 390x4.5	200x4.5	Black	50	220	100	pack

Note: Pictures are not to scale.

Creator: 11.12.2024/JS Released:	Document: DB83871388EN UV cable ties Version: 00	Page 3 of 3
-------------------------------------	---	-------------